



75Ω RF Connector

**PL75**

Compact Push-on Lock Connector
3GHz

**D.FL75**

12G-SDI Standard
Compact 75Ω RF Connector

**BNC75**

12G-SDI Standard
BNC75Ω Connector

**MRF20**

Coaxial/Power/Signal Hybrid
High Speed Transmission

Circular Connectors for Trigger

**HR10**

De Facto Standard
Rated Current: 2A Max.
No. of Pos.: 4-20

**HR25A**

Small Push-Pull Lock Connector
Rated Current: 1A
No. of Pos.: 4-20

IX Connector

**IX**

Small and Robust
Cat.6A Ethernet

USB Connector

**CX**

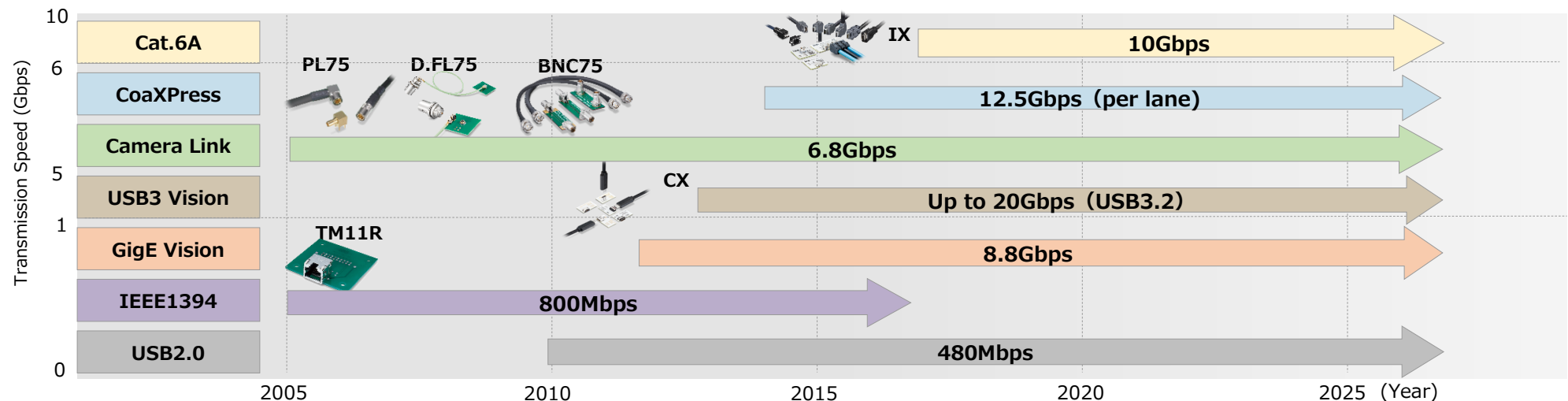
Type-C
USB4 Gen. 2x2

RJ45

**TM11R**

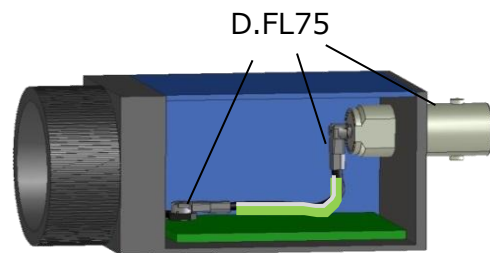
EMI Resistance
Modular Jack Connector

Overview of FA Camera Interfaces and HRS Connectors



Hirose Original Interface Connectors for CoaXPress

◆Flexible Layout

**H.FL75**

3G-SDI Standard
Mated Height: 3.0mm

**BNC(75)J-H.FLJ**

BNC Connector
with H.FL Adaptor

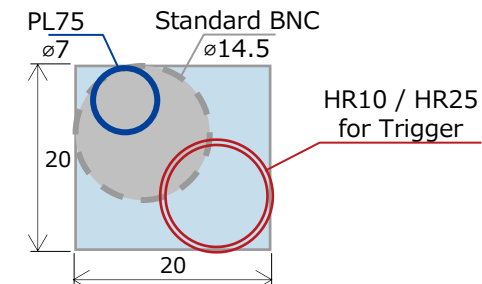
**D.FL75**

12G-SDI Standard
Compact 75Ω RF Connector

**BNC75**

12G-SDI Standard
BNC75Ω Connector

◆Approx. 77% Reduction in PCB Mounting Space Compared to BNC

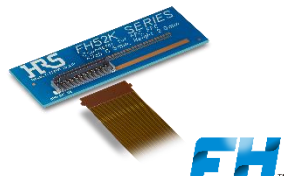
**PL75**

75Ω, Up to 3GHz
Applicable Cable: 1.5C Type

FPC/FFC Connector

**FH28K**

Pitch: 0.5mm, Height: 2.55mm
Depth: 6.4mm, Bottom Contact
No. of Pos.: 10-80

**FH52K**

Pitch: 0.5/1.0mm, Height: 2.0mm
Depth: 5.7mm, Bottom Contact
No. of Pos.: 6-80

**FH34**

Pitch: 0.5mm, Height: 1.0mm
Depth: 3.8mm, Top and Bottom Contact
No. of Pos.: 4-50

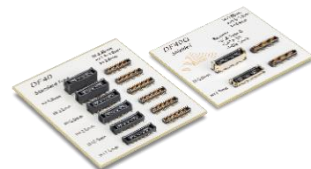
**FH72**

Pitch: 0.3mm, Height: 0.9mm
Depth: 3.5mm, Top Contact
No. of Pos.: 11, 15, 21, 31

Board to Board Connector

**DF12N**

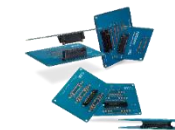
Pitch: 0.5mm
Stacking Height: 3.0-5.0mm
No. of Pos.: 10-80

**DF40**

Pitch: 0.4mm
Stacking Height: 1.5-4.0mm
No. of Pos.: 10-120

**DF40GB**

Shielded Design
Pitch: 0.4mm
Stacking Height: 1.5/3.0/3.5mm
No. of Pos.: 10-70

**FX23/FX23L**

16Gbps High Speed
Pitch: 0.5mm
Stacking Height: 8-30mm
No. of Pos.: 20-120