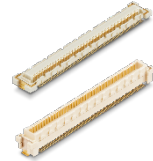




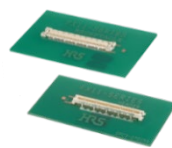
Board-to-Board

FunctionMAX™

**FX10**

16Gbps High Speed
Pitch: 0.5mm
Stacking Height:
4-8mm
No. of Pos.: 80-168
Rated Current: 0.3A

FunctionMAX™

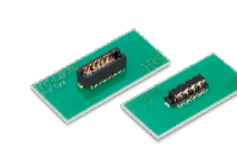
**FX11**

16Gbps High Speed
Pitch: 0.5mm
Stacking Height: 2-3mm
No. of Pos.: 60-140
Rated Current: 0.3A

FunctionMAX™

**ER8**

16Gbps High Speed
Pitch: 0.8mm
Stacking Height:
7-12mm
No. of Pos.: 10-140
Rated Current: 0.5A

**DF12N**

Pitch: 0.5mm
Stacking Height:
3-5mm
No. of Pos.: 10-80
Rated Current: 0.3A

Wire-to-Board

SnapBee™

**DF57**

Pitch: 1.2/2.4mm
Height: 1.4mm
No. of Pos.: 2-6
Rated Current: 3A Max.
Applicable Cable:
26-34 AWG

SnapBee™

**DF61Y**

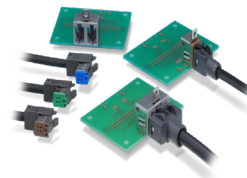
Pitch: 2.2mm
Height: 2.0mm
No. of Pos.: 2, 3
Rated Current: 4A Max.
Applicable Cable:
24-28 AWG

Interface

IX Industrial™

**IX**

IEC Standard
Cat.6A Ethernet (10Gbps)
Rated Current: 1.5A
Applicable Cable: 22-28 AWG

**GT17H/HN**

High Speed 1Gbps
No. of Pos.: 4, 8, 16
Rated Current: 1A
Applicable Cable:
24-28 AWG

**HR30**

IPX7, IPX8
Small Plastic Connector
No. of Pos.: 3, 6, 10, 12
Rated Current: 5A Max.
Applicable Cable:
26-30 AWG

**DH**

No. of Pos.: 17-51
Rated Current: 0.5A
Applicable Cable:
28 AWG

FH™

**FH52K**

Bottom Contact
125°C Heat Resistance
Pitch: 0.5, 1.0mm
Height: 2.0mm
Depth: 5.7mm
No. of Pos.: 6-80
Rated Current: 0.5A

FH™

**FH28K**

Bottom Contact
Robust
Pitch: 0.5mm
Height: 2.55mm
Depth: 7.2mm
No. of Pos.: 10-80
Rated Current: 0.5A