




▲ Portable
Electrocardiograph



▲ Blood Glucose Meter and more...

RF Switch

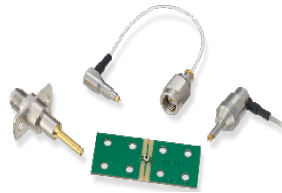

MS-180

RF Switch for Module
Functionality Inspection
Height: 0.85mm
Frequency: 11GHz Max.
Characteristic Impedance: 50Ω

USB



CX


USB Type-C Connector
USB4 Gen.2×2

Micro Coaxial



U.FL

Mated Height: 1.9-2.4mm
Applicable Cable:
ø0.81/0.95/1.13/
1.32/1.37mm

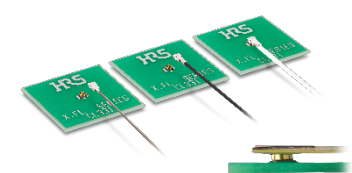

X.FL


Mated Height: 0.94-1.2mm
Applicable Cable:
ø0.5/0.64/0.81/1.13mm

Low Profile Stacking



BM25

Pitch: 0.4mm
Stacking Height: 0.7mm
Depth: 2.6mm
No. of Pos.: 2(Power)
4(Signal)
Rated Current: 10A (Power)
0.3A(Signal)

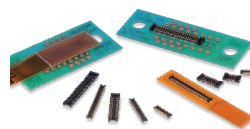

DF37

Pitch: 0.4mm
Stacking Height:
0.98-1.5mm
Depth: 2.98mm
No. of Pos.: 10-70
Rated Current: 0.3A

FPC/FFC



FH34

Top/Bottom Contact
Back Flip
Pitch: 0.5mm
Height: 1.0mm
Depth: 3.8mm
No. of Pos.: 4-50
Rated Current: 0.5A



FH72

One Action **FH**
Top Contact
One Action
Pitch: 0.3mm
Height: 0.9mm
Depth: 3.5mm
No. of Pos.: 11-31
Rated Current: 0.3A



FH58

Top/Bottom Contact
Pitch: 0.2/0.25mm
Height: 0.9mm
Depth: 3.1/3.4mm
No. of Pos.: 7-81
Rated Current: 0.2A