

Stationary Type

① Control Board

② Interface for Probe

④ USB

③ Interface for LCD



Laptop Type

① Control Board

Board-to-Board

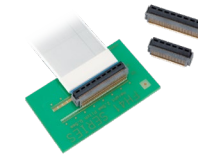
**FX18**

16Gbps High Speed Transmission
Pitch: 0.8mm
No. of Pos.: 40-180

**ER8**

16Gbps High Speed Transmission
Pitch: 0.8mm
No. of Pos.: 10-140

Shielded FFC

**FH41**

3.75Gbps High Speed Transmission
Pitch: 0.5mm

**FH48**

3.75Gbps High Speed Transmission
Vertical Connection
Pitch: 0.5mm

**FH28K**

Pitch: 0.5mm
No. of Pos.: 10-80

② Interface for Probe

Board-to-Board

**FX10**

Pitch: 0.5mm
Stacking Height: 4-8mm
No. of Pos.: 80-168

**FX11**

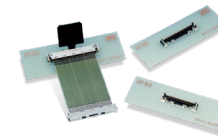
Pitch: 0.5mm
Stacking Height: 2-3mm
No. of Pos.: 60-140

Interface

**EX**

Pitch: 0.8mm
No. of Pos.: 280pos.
Enhanced Grounding Design

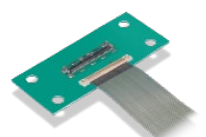
Micro Coaxial

**DF80**

No. of Pos.: 30, 40, 50
Applicable Cable:
32-36 AWG
(Discreet Cable)
40-46 AWG
(Micro Coaxial)

**DF81**

No. of Pos.: 30, 40, 50
Applicable Cable:
34-36 AWG
(Discreet Cable)
36-46 AWG
(Micro Coaxial)

**DF36**

No. of Pos.: 15-50
Applicable Cable:
42-46 AWG
(Micro Coaxial)

③ Interface for LCD

Wire-to-Board

**DH**

2.5Gbps High Speed Transmission
Pitch: 1.0mm

④ USB

Wire-to-Board

**GT17H/HN**

1Gbps High Speed Transmission
USB2.0