


Endoscopic System

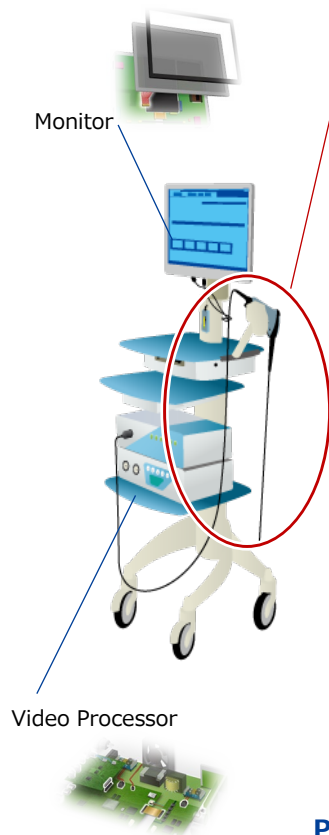


Endoscope



Flexible Endoscope



Rigid Endoscope (Thinner Type)

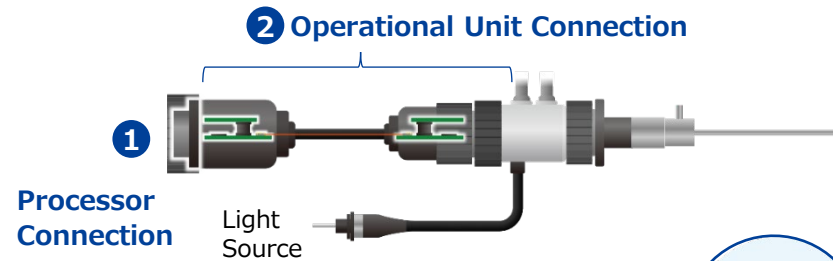


Rigid Endoscope (Thicker Type)

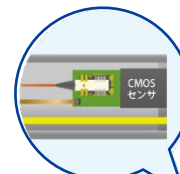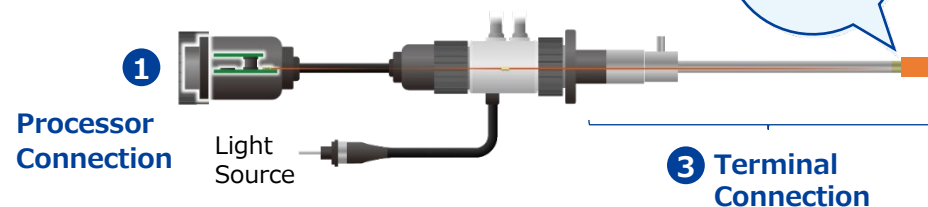1 2 Board-to-Board for Processor/
Operational Unit Connection


DF40

Pitch: 0.4mm
Stacking Height: 1.5-4.0mm
No. of Pos.: 10-120

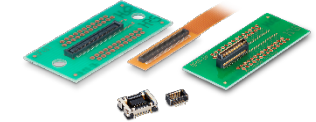


DF40T

125°C High Heat Resistance
Pitch : 0.4mm
Stacking Height: 1.5-7.0mm
No. of Pos.: 10-120
Wide Variations

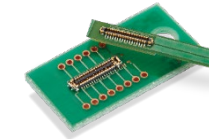

BM28

Pitch: 0.35mm
Depth: 1.7mm
Stacking Height: 0.6mm
No. of Pos.: 2 (Power)
6-60 (Signal)

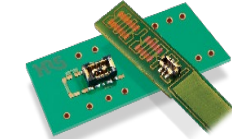

BM29

Pitch: 0.35mm
Depth: 1.5mm
Stacking Height: 0.6mm
No. of Pos.: 2 (Power)
2-24 (Signal)

3 Terminal Connection



BF4M

-Ultra-small Optical
Transmission Module
-6.25Gbps
High Speed Transmission
-EMI Protection



FJ

-Compact optical fiber in-line connector
-Easy and Secure Bayonet Lock
-ø0.5 Bending Resistant Fiber (GI 50/80)
-ø0.9 General Purpose Fiber (GI 50/125)